


Supply plate VABF-B10-20-P1A4-G18

Part number: 576492

FESTO

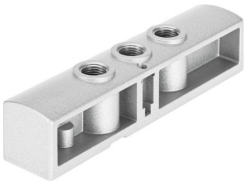

Data sheet

Feature	Value
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	1.4 Nm
Product weight	78 g
Type of mounting	With through-hole
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 3	G1/8
Pneumatic connection, port 5	G1/8
Note on materials	RoHS-compliant
Material supply plate	Die-cast aluminium