


**Sub-base**  
**VMPAC-AP-14-B-1**  
Part number: 576574

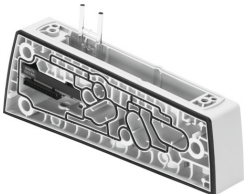

**Data sheet**

| Feature                        | Value                          |
|--------------------------------|--------------------------------|
| Width                          | 32.8 mm                        |
| Length                         | 169 mm                         |
| Grid dimension                 | 26.8 mm                        |
| Max. number of valve positions | 1                              |
| Operating pressure             | -0.9 bar...8 bar               |
| Pilot pressure                 | 3 bar...8 bar                  |
| Corrosion resistance class CRC | 4 - Very high corrosion stress |
| LABS (PWIS) conformity         | VDMA24364-B2-L                 |
| Ambient temperature            | -5 °C...50 °C                  |
| Product weight                 | 160 g                          |
| Pneumatic connection, port 2   | G1/4                           |
| Pneumatic connection, port 4   | G1/4                           |
| Note on materials              | RoHS-compliant                 |
| Material housing               | PA-reinforced                  |