


plastic tubing PCN-4-NT

Part number: 7134
Product to be discontinued

FESTO

Low pressure PVC for use with condensate drains on service units.
Type to be discontinued. Available until 2018. See Support Portal for alternative products.

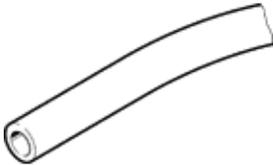

Data sheet

Feature	Value
Outside diameter	6.5 mm
Inside diameter	4 mm
Operating pressure complete temperature range	-0.5 ... 0.25 bar
Ambient temperature	-10 ... 60 °C
Product weight according to length	0.025 kg/m
Colour	neutral
Shore hardness	76
Materials note	Conforms to RoHS
Materials information for tubing	PVC