


Manifold rail
VABM-L1-18G-G38-16-M-G
Part number: 8004910

FESTO

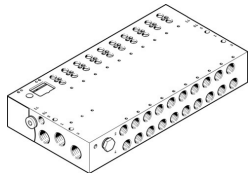

Data sheet

Feature	Value
Grid dimension	19 mm
Mounting position	optional
Max. number of valve positions	16
Approval	c UL us - Recognized (OL)
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...60 °C
Product weight	3861 g
Pilot air port 12/14	G1/8
Pilot exhaust port 82/84	G1/8
Pneumatic connection, port 1	G3/8
Pneumatic connection, port 3	G3/8
Pneumatic connection, port 5	G3/8
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy