


# Manifold block

## VABM-B10-30E-N34-2

Part number: 8026368

FESTO

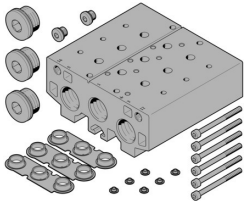

### Data sheet

| Feature                        | Value                         |
|--------------------------------|-------------------------------|
| Grid dimension                 | 32 mm                         |
| Mounting position              | optional                      |
| Max. number of valve positions | 2                             |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L             |
| Product weight                 | 1722 g                        |
| Type of mounting               | With through-hole             |
| Pilot air port 12              | 1/8 NPT                       |
| Pilot air port 14              | 1/8 NPT                       |
| Pneumatic connection, port 1   | 3/4 NPT                       |
| Pneumatic connection, port 3   | 3/4 NPT                       |
| Pneumatic connection, port 5   | 3/4 NPT                       |
| Note on materials              | RoHS-compliant                |
| Material manifold rail         | Wrought aluminium alloy       |