


Check valve VMPA2-RV

Part number: 8039821

FESTO

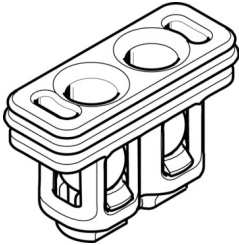

Data sheet

Feature	Value
Valve function	Piloted non-return function
Type of actuation	Pneumatic
Type of mounting	Clip
Standard nominal flow rate (standardised to DIN 1343)	330 l/min
Operating pressure	0.05 MPa...0.8 MPa 0.5 bar...8 bar
Pilot pressure	0.05 MPa...0.8 MPa 0.5 bar...8 bar 7.25 psi...116 psi
Ambient temperature	-5 °C...50 °C
Material housing	POM
Operating medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Mounting position	optional
Type act., cont. n.-r. func.	Pneumatic
Operating pressure complete temperature range	0.5 bar...8 bar
Note on operating and pilot medium	Lubricated operation possible (in which case lubricated operation will always be required)
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Storage temperature	-20 °C...40 °C
Media temperature	-5 °C...50 °C
Pilot medium	Compressed air to ISO 8573-1:2010 [7:4:4]
Product weight	0.19 g
Note on materials	RoHS-compliant
Material seals	NBR