


Sub-base
VMPA14-FB-AP-4-1-T1
Part number: 8043928

FESTO

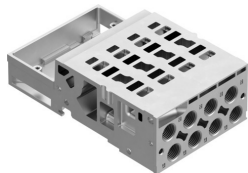

Data sheet

Feature	Value
Width	65.5 mm
Length	107.3 mm
Grid dimension	14.8 mm 14.9 mm
Max. number of valve positions	4
Operating pressure	-0.09 MPa...1 MPa -0.9 bar...10 bar
Pilot pressure	0.3 MPa...0.8 MPa 3 bar...8 bar
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-5 °C...50 °C
Product weight	250 g
Pneumatic connection, port 2	G1/8
Pneumatic connection, port 4	G1/8
Note on materials	RoHS-compliant
Material sub-base	Die-cast aluminium