


**Manifold rail**  
**VABM-L1-14HWS2-G14-24-GR**  
Part number: 8058347

**FESTO**

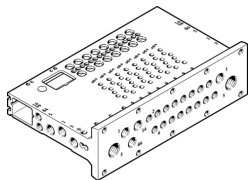

**Data sheet**

| Feature                        | Value                         |
|--------------------------------|-------------------------------|
| Grid dimension                 | 16 mm                         |
| Mounting position              | optional                      |
| Max. number of valve positions | 24                            |
| Approval                       | c UL us - Recognized (OL)     |
| Corrosion resistance class CRC | 2 - Moderate corrosion stress |
| LABS (PWIS) conformity         | VDMA24364-B1/B2-L             |
| Storage temperature            | -20 °C...60 °C                |
| Pilot air port 12/14           | M5                            |
| Pilot exhaust port 82/84       | M5                            |
| Pneumatic connection, port 1   | G1/4                          |
| Pneumatic connection, port 2   | G1/8                          |
| Pneumatic connection, port 3   | G1/4                          |
| Pneumatic connection, port 4   | G1/8                          |
| Pneumatic connection, port 5   | G1/4                          |
| Note on materials              | RoHS-compliant                |
| Material manifold rail         | Wrought aluminium alloy       |