


Axial kit
EAMM-A-L48-92RA
Part number: 8063478

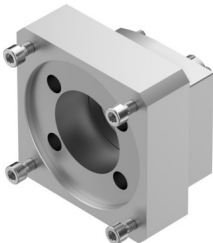

Data sheet

Feature	Value
Nominal length	57.3 mm
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	14.5 kgmm ²
Transmittable torque	12.5 Nm
Product weight	898 g
Interface code, actuator	L48
Interface code, motor in	92RA
Note on materials	RoHS-compliant