


**Axial kit**  
**EAMM-A-L95-120GC**  
Part number: 8063531

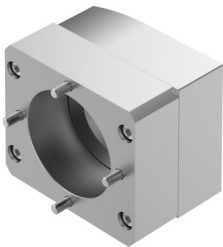

**Data sheet**

| Feature                  | Value                 |
|--------------------------|-----------------------|
| Nominal length           | 95.4 mm               |
| Mounting position        | optional              |
| Max. rotational speed    | 4500 rpm              |
| LABS (PWIS) conformity   | VDMA24364-B2-L        |
| Storage temperature      | -25 °C...60 °C        |
| Relative air humidity    | 0 - 95%               |
| Degree of protection     | IP40                  |
| Ambient temperature      | -10 °C...60 °C        |
| Mass moment of inertia   | 374 kgmm <sup>2</sup> |
| Transmittable torque     | 192 Nm                |
| Product weight           | 3608 g                |
| Interface code, actuator | L95                   |
| Interface code, motor in | 120GC                 |
| Note on materials        | RoHS-compliant        |