


Manifold rail
VABM-P7-18M-G18-M5-8
Part number: 8076390

FESTO

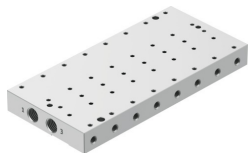

Data sheet

Feature	Value
Grid dimension	18 mm
Design	Connection direction at side
Max. number of valve positions	8
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Max. tightening torque for valve mounting	0.6 Nm
Product weight	360 g
Pneumatic connection, port 1	G1/8
Pneumatic connection, port 2	M5
Note on materials	RoHS-compliant
Material manifold rail	Wrought aluminium alloy