


Axial kit
EAMM-A-V32-60AA
Part number: 8092271

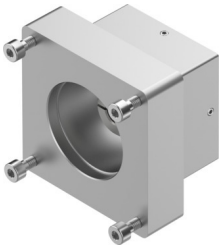

Data sheet

Feature	Value
Nominal length	42 mm
Mounting position	optional
Max. rotational speed	10000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	0.19 kgmm ²
Transmittable torque	1.5 Nm
Product weight	203 g
Interface code, actuator	V32
Interface code, motor in	60AA
Note on materials	RoHS-compliant