


Sub-base VABS-P16-10S-M5

Part number: 8097804

FESTO

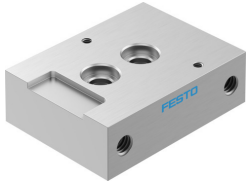

Data sheet

Feature	Value
Construction width	26 mm
Mounting position	optional
Special characteristics	Oxygen-compatible to DIN EN 1797
Max. number of valve positions	1
Operating pressure	0 bar...7 bar
Operating medium	Compressed air to ISO 8573-1:2010 [6:3:4] Inert gases Air Oxygen Nitrogen
Note on operating and pilot medium	Lubricated operation not possible Maximum particle size 5 µm
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-20 °C...70 °C
Media temperature	-10 °C...60 °C
Relative air humidity	0 - 60% Non-condensing
Ambient temperature	-10 °C...60 °C
Product weight	25 g
Type of mounting	With through-hole Via female thread
Pneumatic connection, port 1	M5
Pneumatic connection, port 2	M5
Note on materials	RoHS-compliant
Material sub-base	Wrought aluminium alloy