


Axial kit
EAMM-A-D40-58AA
Part number: 8105928

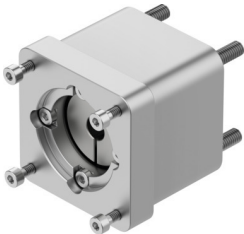

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	12.5 Nm
Product weight	354 g
Interface code, actuator	D40
Interface code, motor in	58AA
Note on materials	RoHS-compliant