


Axial kit
EAMM-A-D60-90GA
Part number: 8105944

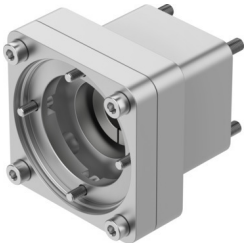

Data sheet

Feature	Value
Mounting position	optional
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	34.8 kgmm ²
Transmittable torque	21 Nm
Product weight	1579 g
Interface code, actuator	D60
Interface code, motor in	90GA
Note on materials	RoHS-compliant