


**Axial kit**  
**EAMM-A-D40-50GA**  
Part number: 8117076

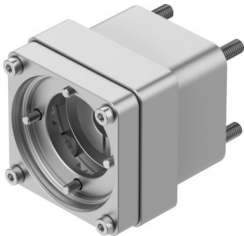

**Data sheet**

| Feature                  | Value                  |
|--------------------------|------------------------|
| Mounting position        | optional               |
| LABS (PWIS) conformity   | VDMA24364-B2-L         |
| Storage temperature      | -25 °C...60 °C         |
| Relative air humidity    | 0 - 95%                |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C...60 °C         |
| Mass moment of inertia   | 5.87 kgmm <sup>2</sup> |
| Transmittable torque     | 12.5 Nm                |
| Product weight           | 411 g                  |
| Interface code, actuator | D40                    |
| Interface code, motor in | 50GA                   |
| Note on materials        | RoHS-compliant         |