


Valve

VOFC-LT-M32C-MC-N14-FN

Part number: 8122933

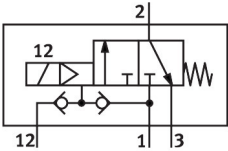

Data sheet

Feature	Value
Standard nominal flow rate (standardised to DIN 1343)	703 l/min
Operating pressure	0.1 MPa...0.8 MPa 1 bar...8 bar 14.5 psi...116 psi
Degree of protection	IP65
Certificate issuing authority	TÜV 968/V 1251.00/24
Safety function	Safe venting
Safety Integrity Level (SIL)	Up to SIL 3 High Demand mode To SIL 3 Low Demand mode
Note on operating pressure	0 - 0.8 MPa with ext. pilot air
Explosion protection	Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Note on materials	RoHS-compliant