


# Retainer VMPA14-FTI

Part number: 8129127

FESTO

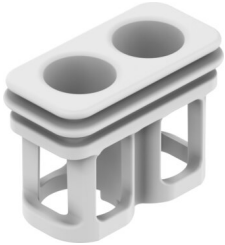

## Data sheet

| Feature                            | Value                                                                                      |
|------------------------------------|--------------------------------------------------------------------------------------------|
| Size                               | 14                                                                                         |
| Mounting position                  | optional                                                                                   |
| Size of pack                       | 10                                                                                         |
| Operating pressure                 | -0.09 MPa...1 MPa<br>-0.9 bar...10 bar<br>-13.05 psi...145 psi                             |
| Operating medium                   | Compressed air to ISO 8573-1:2010 [7:4:4]                                                  |
| Note on operating and pilot medium | Lubricated operation possible (in which case lubricated operation will always be required) |
| LABS (PWIS) conformity             | VDMA24364-B1/B2-L                                                                          |
| Storage temperature                | -20 °C...40 °C                                                                             |
| Media temperature                  | -5 °C...60 °C                                                                              |
| Ambient temperature                | -5 °C...60 °C                                                                              |
| Product weight                     | 0.1 g                                                                                      |
| Type of mounting                   | Clamped                                                                                    |
| Note on materials                  | RoHS-compliant                                                                             |
| Material retaining bracket         | POM                                                                                        |