


Manifold block

VABS-S7-RB-B-G14-VDE2-R12

Part number: 8141067

FESTO

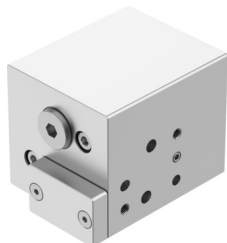

Data sheet

Feature	Value
Mounting position	optional
Pilot air supply	External Internal
Operating pressure	0 MPa...1 MPa 0 bar...10 bar
Operating medium	Compressed air to ISO 8573-1:2010 [:-::-]
Corrosion resistance class CRC	4 - Very high corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP65 In assembled state
Product weight	750 g
Type of mounting	With through-hole
Pilot air port 12	G1/4
Pneumatic connection, port 1	G1/4
Pneumatic connection, port 2	VDI/VDE 3847 (NAMUR)
Pneumatic connection, port 3	G1/4
Note on materials	RoHS-compliant
Material sub-base	Ematal coated aluminium
Material seals	NBR