


# Double nipple NPFC-DS-G18-G14-M

Part number: 8142584

**FESTO**

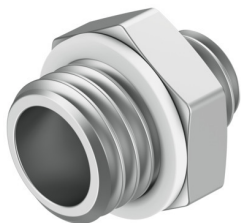

## Data sheet

| Feature                                           | Value                                    |
|---------------------------------------------------|------------------------------------------|
| Material threaded fitting                         | Nickel-plated brass                      |
| Size of pack                                      | 10                                       |
| Operating pressure                                | -0.95 bar...10 bar                       |
| Operating medium                                  | Compressed air to ISO 8573-1:2010 [:-:-] |
| Corrosion resistance class CRC                    | 1 - Low corrosion stress                 |
| LABS (PWIS) conformity                            | VDMA24364-B2-L                           |
| Ambient temperature                               | -10 °C...60 °C                           |
| Nominal tightening torque, pneumatic connection 1 | 9.05 Nm                                  |
| Nominal tightening torque, pneumatic connection 2 | 10.55 Nm                                 |
| Tolerance for nominal tightening torque           | ± 20%                                    |
| Product weight                                    | 16.23 g                                  |
| Pneumatic connection, port 1                      | G1/4                                     |
| Pneumatic connection, port 2                      | G1/8                                     |
| Note on materials                                 | RoHS-compliant                           |
| Material seals                                    | PVC                                      |