


Power supply unit CACN-3A-7-10-G2

Part number: 8149584

FESTO

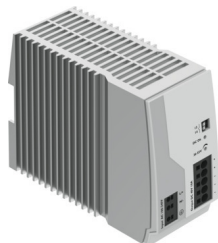

Data sheet

Feature	Value
Width	68 mm
Height	130 mm
Length	160 mm
Mounting position	Free convection
Primary supply	Single-phase
Input current	2.4 - 5.6 A
Nominal output voltage DC	48 V
Nominal output current	10 A
Input voltage range AC	100 V...240 V
Power failure bridging	15 ms
Mains frequency	45 Hz...65 Hz
Approval	c UL us listed (OL)
CE mark (see declaration of conformity)	To EU EMC Directive To EU Low Voltage Directive
LABS (PWIS) conformity	VDMA24364 zone III
Storage temperature	-40 °C...85 °C
Relative air humidity	95 %
Degree of protection	IP20
Ambient temperature	-25 °C...70 °C
Product weight	1603 g
Type of mounting	With H-rail
Note on materials	RoHS-compliant