


Solenoid coil VACF-B-E1-1

Part number: 8153947

FESTO

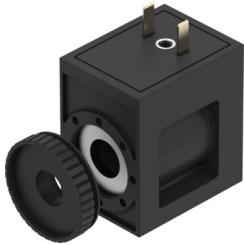

Data sheet

Feature	Value
Type of actuation	Electric
Mounting position	optional
Conforms to standard	IEC 61010-1
Duty cycle	100%
Insulation material class	H
Insulation material class of enamelled wire	H
Characteristic coil data	24 V DC: 3.3 W
Permissible voltage fluctuations	+/- 10 %
Approval	c UL us - Recognized (OL)
Certificate issuing authority	UL MH18122
Restrictions for environmental and media temperature	-20 - 50°C
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Media temperature	-20 °C...50 °C
Degree of protection	IP65
Ambient temperature	-20 °C...60 °C
Product weight	48.5 g
Electrical connection 1, connection type	Plugs
Electrical connection 1, connector system	Plug pattern type C to industry standard, 9.4 mm
Type of mounting	Via knurled nut
Note on materials	RoHS-compliant
Material housing	PA Steel
Material solenoid coil	Copper Steel Thermoplastic
Material winding	Copper