


Guide unit EAGF-P2-KF-45-

Part number: 8158133

FESTO

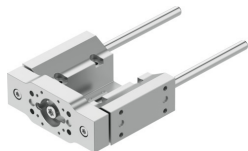

Data sheet

Feature	Value
Size	45
Stroke	1 mm...300 mm
Reversing backlash theoretical	0 µm
Mounting position	optional
Guide	Recirculating ball bearing guide
Design	Guidance
Max. acceleration	25 m/s ²
Max. speed	1 m/s
Corrosion resistance class CRC	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364 zone III
Degree of protection	IP40
Ambient temperature	0 °C...60 °C
Max. force Fy	320 N
Max. force Fy static	415 N
Max. force Fz	320 N
Max. force Fz static	415 N
Max. moment Mx	15 Nm
Max. torque Mx static	19 Nm
Max. moment My	10 Nm
Max. torque My static	12 Nm
Max. moment Mz	10 Nm
Max. torque Mz static	12 Nm
Displacement force	2 N
Moving mass for 0 mm stroke	342 g
Basic weight for 0 mm stroke	1037 g
Additional weight per 10 mm stroke	12.3 g
Additional moving mass per 10 mm stroke	12.3 g
Centre of gravity at 0 mm stroke	25 mm
Centre of gravity additional of moving mass per 10 mm	4.3 mm
Type of mounting	Via female thread
Note on materials	RoHS-compliant

Feature	Value
Material guide component	Tempered steel Hard-chrome-plated
Material housing	Wrought aluminium alloy Anodised
Material yoke plate	Wrought aluminium alloy Anodised