


Axial kit
EAMM-A-X48-57A
Part number: 8165289

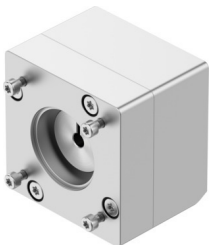

Data sheet

Feature	Value
Mounting position	optional
Max. rotational speed	8000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transmittable torque	7.5 Nm
Product weight	614 g
Interface code, actuator	X48
Interface code, motor in	57A
Note on materials	RoHS-compliant