


# Axial kit EAMM-A-L48-50GA-G2

Part number: 8188639

FESTO

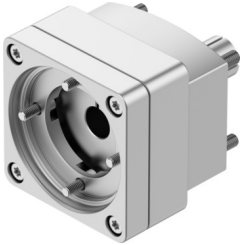

## Data sheet

Feature	Value
Nominal length	42.5 mm
Mounting position	optional
Max. rotational speed	6000 rpm
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95%
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Mass moment of inertia	39 kgmm <sup>2</sup>
Transmittable torque	21 Nm
Product weight	415 g
Interface code, actuator	L48
Interface code, motor in	50GA
Note on materials	RoHS-compliant