


**Guide unit**  
**FEN-25-160-GF**  
Part number: 8204056

**FESTO**

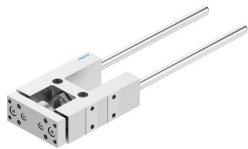

**Data sheet**

| Feature                  | Value                                                |
|--------------------------|------------------------------------------------------|
| Size                     | 25                                                   |
| Stroke                   | 160 mm                                               |
| Mounting position        | optional                                             |
| Guide                    | Plain-bearing guide                                  |
| Design                   | Guidance                                             |
| Explosion protection     | The information in the certificate must be observed! |
| LABS (PWIS) conformity   | VDMA24364-B2-L                                       |
| Ambient temperature      | -20 °C...80 °C                                       |
| Displacement force       | 15 N                                                 |
| Moving mass              | 461 g                                                |
| Product weight           | 1058 g                                               |
| Type of mounting         | Via female thread                                    |
| Note on materials        | RoHS-compliant                                       |
| Material guide component | High-alloy steel                                     |
| Material housing         | Anodised wrought aluminium alloy                     |
| Material yoke plate      | Anodised wrought aluminium alloy                     |