


Adapter plate

OAMC-PA-G14-4

Part number: 8205196

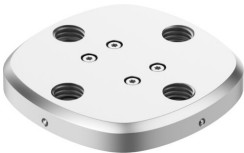

Data sheet

Feature	Value
Material mounting bracket	Anodised aluminium
Mounting position	optional
Design	Sub-base
Operating medium	Compressed air to ISO 8573-1:2010 [:-::-]
Corrosion resistance class CRC	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque	1 Nm
Product weight	215 g
Type of mounting	Direct mounting via thread
Suction cup mounting	Female thread G1/4
Suction cup mounting, quantity	4
Note on materials	RoHS-compliant
Material seals	NBR
Material plate	Anodised wrought aluminium alloy