


Inline filter **OAFA-C-Q4-E-E** Part number: 8212638

FESTO

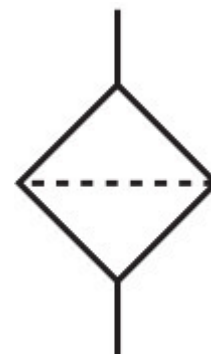

Data sheet

| Feature | Value |
|--|--|
| Nominal size | 4 mm |
| Instructions on use | The housing should not be cleaned with polar solvents (such as alcohol). |
| Mounting position | optional |
| Grade of filtration | 40 µm |
| Operating pressure | -0.1 MPa...1 MPa -1 bar...10 bar -14.5 psi...145 psi |
| Operating medium | Air |
| Corrosion resistance class CRC | 1 - Low corrosion stress |
| LABS (PWIS) conformity | VDMA24364 zone III |
| Suitability for the production of Li-ion batteries | Suitable for battery production according to the Festo internal definition of the degree of severity F1A with restrictions regarding the use of Cu/Zn/Ni |
| Ambient temperature | 0 °C...60 °C |
| Product weight | 5.4 g |
| Type of mounting | In-line installation |
| Pneumatic connection | For tubing O.D. 4 mm |
| Note on materials | RoHS-compliant |
| Material seals | HNBR |
| Material filter | PE |
| Material housing | PA |