


# Adding counter PZA-E-C

Part number: 8606

**FESTO**

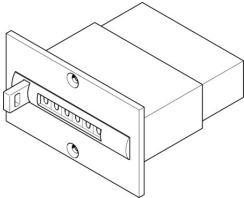

## Data sheet

| Feature                            | Value                                                              |
|------------------------------------|--------------------------------------------------------------------|
| Design                             | Mechanical sequence counter with pneumatic drive                   |
| Type of reset                      | Pushbutton or pneumatic signal                                     |
| Display                            | 6-digit                                                            |
| Drop-off pressure drive            | < 0.15 bar                                                         |
| Drop-off pressure reset            | < 0.15 bar                                                         |
| Response pressure drive            | > 0.8 bar                                                          |
| Response pressure reset            | 2 bar                                                              |
| Operating pressure                 | 2 bar...8 bar                                                      |
| Min. reset pressure                | 2 bar                                                              |
| Min. pulse length drive            | 8 ms                                                               |
| Min. pulse length reset            | 150 ms                                                             |
| Min. pause period drive            | 10 ms                                                              |
| Min. pause period reset            | 50 ms                                                              |
| Explosion protection               | Zone 1 (ATEX)<br>Zone 2 (ATEX)<br>Zone 21 (ATEX)<br>Zone 22 (ATEX) |
| Operating medium                   | Compressed air to ISO 8573-1:2010 [7:4:4]                          |
| Note on operating and pilot medium | Lubricated operation possible                                      |
| LABS (PWIS) conformity             | VDMA24364-B1/B2-L                                                  |
| Ambient temperature                | 0 °C...60 °C                                                       |
| Product weight                     | 70 g                                                               |
| Type of mounting                   | Front panel mounting                                               |
| Pneumatic connection               | M5                                                                 |
| Material housing                   | PA                                                                 |