


Suction cup insert OASI-40

Part number: 1048881

FESTO

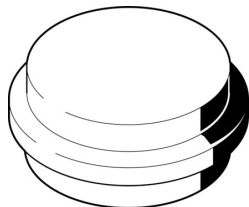

Data sheet

Feature	Value
Operating pressure	0 bar...0.95 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::-]
LABS (PWIS) conformity	VDMA24364-A1-L
For use in the food industry	See supplementary material information
Ambient temperature	5 °C...50 °C
Product weight	2.9 g
Type of mounting	Plug-in
Note on materials	RoHS-compliant
Suction-cup insert material	PE
Ejector pulse suitability	5 bar
Mounting position	Inner thinning