


Filter muffler LFU-1

Part number: 10495

FESTO

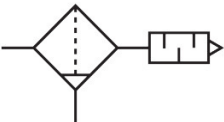

Data sheet

Feature	Value
Inlet pressure 1	0 bar...16 bar
Inlet pressure 1 MPa	0 MPa...1.6 MPa
Inlet pressure 1 psi	0 psi...232 psi
Flow rate with respect to atmosphere	12500 l/min
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Type of mounting	Screw-in
Pneumatic connection	G1
Note on materials	RoHS-compliant