


**Parallel kit**  
**EAMM-U-50-S38-40A-78**  
Part number: 1217708

**FESTO**

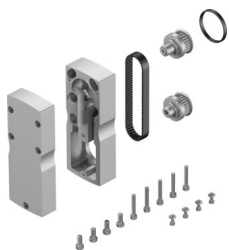

**Data sheet**

| Feature                  | Value                  |
|--------------------------|------------------------|
| Size                     | 50                     |
| Mounting position        | Any                    |
| Gear ratio               | 1:1                    |
| Max. rotational speed    | 6000 rpm               |
| LABS (PWIS) conformity   | VDMA24364 zone III     |
| Storage temperature      | -25 °C...60 °C         |
| Relative air humidity    | 0 - 95 %               |
| Degree of protection     | IP40                   |
| Ambient temperature      | -10 °C...60 °C         |
| Mass moment of inertia   | 12.1 kgmm <sup>2</sup> |
| No-load driving torque   | 0.01 Nm                |
| Transferable torque      | 1 Nm                   |
| Product weight           | 580 g                  |
| Interface code, actuator | S38                    |
| Interface code, motor in | 40A                    |
| Note on materials        | RoHS-compliant         |