


Pneumatic muffler AMTC-P-PC10

Part number: 1224460

FESTO

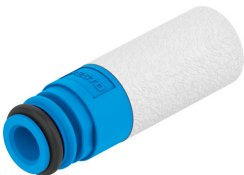

Data sheet

Feature	Value
Mounting position	Any
Pack size	1
Operating pressure	0 MPa...1 MPa 0 bar...10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
Information on operating and pilot media	Operation with oil lubrication possible
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Noise level	58 dB(A)
Ambient temperature	-5 °C...60 °C
Product weight	2 g
Pneumatic connection	Cartridge 10 mm
Cushioning insert material	PE
Material of screwed plug	PE
Note on materials	RoHS-compliant