


Pneumatic shock absorber YSRW-DGC-40/50-B

Part number: 1232870

FESTO

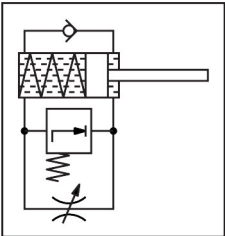

Data sheet

Feature	Value
Size	40 50
Cushioning	Self-adjusting Soft characteristic curve
Mounting position	Any
Position sensing	None
Max. impact velocity	3 m/s
Mode of operation	Pushing Single-acting
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-10 °C...80 °C
Type of mounting	With lock nut
Note on materials	RoHS-compliant
Piston rod material	High-alloy steel