


**Sub-base**  
**VABS-C8-12XB-QX-B**  
Part number: 1236025

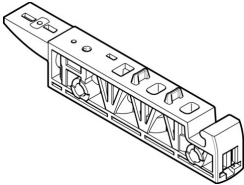

**Data sheet**

Feature	Value
Width	12 mm
Max. no. of valve positions	1
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.48 Nm...0.72 Nm
Max. tightening torque for wall mounting	1.3 Nm
Product weight	15 g
Pilot air port 12/14	Prepared for cartridge
Pneumatic connection 1	Prepared for cartridge
Pneumatic connection 3	Prepared for cartridge
Pneumatic connection 5	Prepared for cartridge
Note on materials	RoHS-compliant
Manifold rail material	PA-reinforced