


# Manifold rail

## VABM-C8-12E-G14-35-PT-L

Part number: 1247987

FESTO

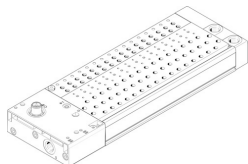

## Data sheet

Feature	Value
Width dimension	12 mm
Max. no. of valve positions	35
UKCA marking (see declaration of conformity)	To UK instructions for EMC To UK RoHS instructions
Corrosion resistance class (CRC)	0 - No corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Max. tightening torque for valve mounting	0.6 Nm
Max. tightening torque for wall mounting	5 Nm
Product weight	2138 g
Pneumatic connection 1	G1/4
Pneumatic connection 3	G1/4
Pneumatic connection 5	G1/4