


# Clamping module EV-15/63-4

Part number: 13290

FESTO

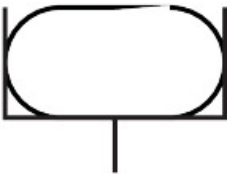

## Data sheet

Feature	Value
Stroke	4 mm
Clamping area	15x63
Mounting position	Any
Mode of operation	Single-acting
Operating pressure	0.2 MPa...0.6 MPa 2 bar...6 bar 29 psi...87 psi
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Suitability for the production of Li-ion batteries	Metals with more than 5% by mass of copper are excluded from use. Exception are printed circuit boards, cables, electrical connectors and coils
Ambient temperature	-20 °C...40 °C
Product weight	65 g
Type of mounting	With through-hole
Pneumatic connection	M5
Housing material	Die-cast aluminum
Diaphragm material	TPE-U(PU)