


Barb fitting CRCN-1/4-PK-4

Part number: 13972

FESTO

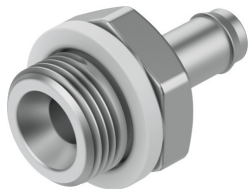

Data sheet

Feature	Value
Nominal width	3.2 mm
Type of seal on screwed plug	Sealing ring
Pack size	1
Operating pressure for entire temperature range	-0.95 bar...10 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7:::]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS (PWIS) conformity	VDMA24364-B2-L
For use in the food industry	See supplementary material information
Ambient temperature	0 °C...60 °C
Product weight	17.73 g
Pneumatic connection 1	External thread G1/4
Pneumatic connection 2	for pneumatic tubing outside diameter 6 mm
Note on materials	RoHS-compliant
Housing material	High-alloy stainless steel
Material of threaded seal	PA-reinforced TPE-U(PU)