


Commander FSSC-12

Part number: 13985

FESTO

Pneumatic operator panel for Quickstepper, with manual operation for quick and reliable actuation. Module includes built-in command functions
Type to be discontinued. Available until 2009.

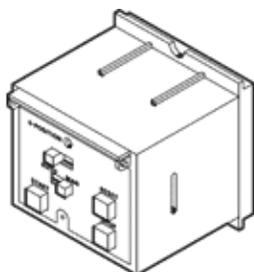

Data sheet

Feature	Value
Nominal size	2.5 mm
Design structure	Combinable sequencer
Acknowledgement drop-off pressure	≤ 0.5 bar
Acknowledgement response pressure	≥ 1.5 bar
Working pressure	2 ... 6 bar
Standard nominal flow rate	60 l/min
Min. acknowledgement pulse length	50 ms
Operating medium	Filtered, unlubricated compressed air, 5 μ m filtration
Ambient temperature	5 ... 40 °C
Product weight	450 g
Materials information for seals	NBR
Materials information, housing	ABS