


**End plate kit**  
**NEV-3DA/DB-NPT**  
Part number: 13997

**FESTO**

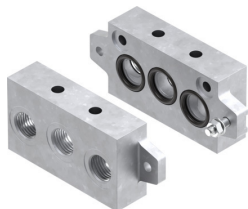

**Data sheet**

| Feature                                  | Value  |
|--|--|
| Width                                    | 190 mm   |
| Operating pressure                       | 0 bar...16 bar   |
| Operating medium                         | Compressed air as per ISO 8573-1:2010 [7:-:-]                      |
| Information on operating and pilot media | Operation with oil lubrication possible (required for further use) |
| LABS (PWIS) conformity                   | VDMA24364-B1/B2-L  |
| Temperature of medium                    | -10 °C...60 °C   |
| Ambient temperature                      | -10 °C...60 °C   |
| Sub-base mounting type                   | With through-hole  |
| Pneumatic valve mounting type            | Screw-in   |
| Pneumatic connection 1                   | NPT1-11 1/2  |
| Pneumatic connection 3                   | NPT1-11 1/2  |
| Pneumatic connection 5                   | NPT1-11 1/2  |