


Axial kit EAMM-A-D40-67A

Part number: 1454243

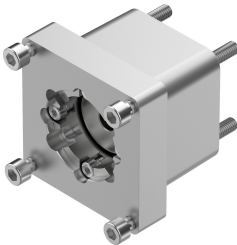

Data sheet

Feature	Value
Mounting position	Any
LABS (PWIS) conformity	VDMA24364-B2-L
Storage temperature	-25 °C...60 °C
Relative air humidity	0 - 95 %
Degree of protection	IP40
Ambient temperature	-10 °C...60 °C
Transferable torque	12.5 Nm
Product weight	440 g
Interface code, actuator	D40A D40B D40C
Interface code, motor in	67A
Note on materials	RoHS-compliant