


# Axial kit EAMM-A-R27-67A

Part number: 1456619

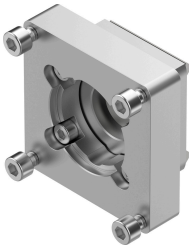

## Data sheet

| Feature                  | Value          |
|--------------------------|----------------|
| Mounting position        | Any            |
| LABS (PWIS) conformity   | VDMA24364-B2-L |
| Storage temperature      | -25 °C...60 °C |
| Relative air humidity    | 0 - 95 %       |
| Degree of protection     | IP40           |
| Ambient temperature      | -10 °C...60 °C |
| Transferable torque      | 2 Nm           |
| Product weight           | 280 g          |
| Interface code, actuator | R27            |
| Interface code, motor in | 67A            |
| Note on materials        | RoHS-compliant |