


# Flange mounting EAHH-V2-100-R1

Part number: 1502307

FESTO

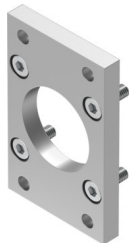

## Data sheet

| Feature  | Value   |
|--|---|
| Size   | 100   |
| Based on norm                                      | ISO 15552   |
| Corrosion resistance class (CRC)                   | 3 - High corrosion stress   |
| LABS (PWIS) conformity                             | VDMA24364-B2-L  |
| Suitability for the production of Li-ion batteries | Metals with more than 5% by mass of copper, zinc or nickel by mass are excluded from use. Exceptions are nickel in steel, chemically nickel-plated surfaces, printed circuit boards, cables, electrical plug connectors and coils |
| Cleanroom class                                    | Statically installed element, no meaningful evaluation possible according to ISO 14644-1  |
| Max. load capacity                                 | 17 kN   |
| Product weight                                     | 1880 g  |
| Note on materials                                  | RoHS-compliant  |
| Plate material                                     | High-alloy stainless steel  |
| Material of screws                                 | High-alloy stainless steel  |