


# Clamping module EV-12-3

Part number: 150681

FESTO

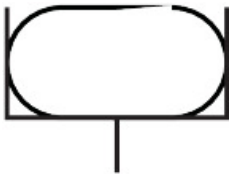

## Data sheet

| Feature                | Value                                        |
|------------------------|----------------------------------------------|
| Stroke                 | 3 mm                                         |
| Clamping area          | Ø 12                                         |
| Mounting position      | Any                                          |
| Mode of operation      | Single-acting                                |
| Operating pressure     | 0.6 MPa<br>6 bar<br>87 psi                   |
| Operating medium       | Compressed air as per ISO 8573-1:2010 [7::-] |
| LABS (PWIS) conformity | VDMA24364-B1/B2-L                            |
| Ambient temperature    | -10 °C...40 °C                               |
| Product weight         | 11 g                                         |
| Type of mounting       | With through-hole                            |
| Pneumatic connection   | M3                                           |
| Housing material       | Die-cast aluminum                            |
| Diaphragm material     | TPE-U(PU)                                    |