


# One-way flow control valve GRLA-10-UNF-B

Part number: 151572

**FESTO**

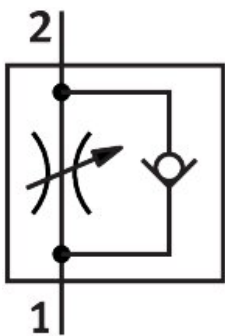

## Data sheet

Feature	Value
Valve function	Exhaust air flow control non-return function
Pneumatic connection 1	10-32 UNF-2B
Pneumatic connection 2	10-32 UNF-2A
Adjusting element	Slotted screw
Type of mounting	Screw-in
Operating pressure	0.2 bar...10 bar
Ambient temperature	-10 °C...60 °C
Explosion prevention and protection	Observe the information on the certificate Zone 1 (ATEX) Zone 2 (ATEX) Zone 21 (ATEX) Zone 22 (ATEX)
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B2-L
Cleanroom suitability, measured according to ISO 14644-14	Class 4 according to ISO 14644-1
Temperature of medium	-10 °C...60 °C
Nominal width	2 mm
Note on materials	RoHS-compliant