


Linear actuator
DGO-1/2"- -P-A-B
Part number: 15227

FESTO

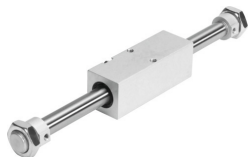

Data sheet

Feature	Value
Stroke	0.04 in...157 in
Piston diameter	1/2"
Cushioning	Elastic cushioning rings/pads at both ends
Guide	Sliding guide
Operating pressure	2 bar...7 bar
Mode of operation	Double-acting
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...60 °C
Theoretical force at 6 bar, retracting	68 N
Theoretical force at 6 bar, advancing	68 N
Pneumatic connection	10-32 UNF-2B