


Linear actuator
DGO-1 1 1/4"- -PPV-A-B
Part number: 15231

FESTO

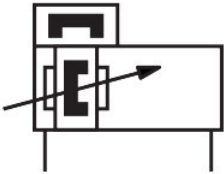

Data sheet

Feature	Value
Stroke	0.04 in...157 in
Piston diameter	1 1/4"
Cushioning	Pneumatic cushioning, adjustable at both ends
Guide	Sliding guide
Driver principle	Force-locking (magnetic)
Operating pressure	1.4 bar...7 bar
Mode of operation	Double-acting
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B2-L
Ambient temperature	-20 °C...60 °C
Cushioning length	20 mm
Pneumatic connection	1/8 NPT