


Bellows suction cup VASB-125-3/8-PUR

Part number: 152610

FESTO

With sealing ring OL.

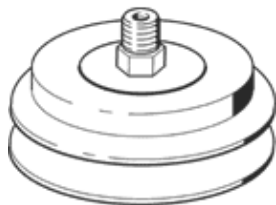

Data sheet

Feature	Value
Nominal size	7 mm
suction cup diameter	125 mm
Effective suction diameter	105 mm
Design structure	Vacuum connection at top round, bellows 1.5 convolutions
Operating medium	Atmospheric air
Ambient temperature	-20 ... 60 °C
Breakaway force at 70% vacuum	606 N
Mounting thread	G3/8
suction cup mounting	G3/8
Vacuum connection	G3/8
Shore hardness	62
Materials information for screw-in stud	Wrought Aluminum alloy
Materials information for suction cup	TPE-U(PU)