


Ball valve
QH-QS-6
Part number: 153484

FESTO

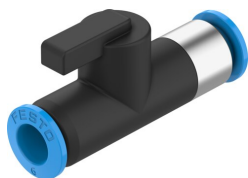

Data sheet

Feature	Value
Valve function	2/2 bistable
Pneumatic connection 1	QS-6
Pneumatic connection 2	QS-6
Actuation type	Manual
Type of mounting	Line installation
Normal nominal flow rate (normalized to DIN 1343)	533 l/min
Nominal width	4 mm
Operating pressure	-0.1 MPa...1 MPa -1 bar...10 bar
Ambient temperature	0 °C...60 °C
Housing material	PBTP
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Sealing principle	Soft
Structural design	Ball valve
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Product weight	12 g
Note on materials	RoHS-compliant