


Barb tubing fitting N-3/4-P-13-MS

Part number: 15637

FESTO

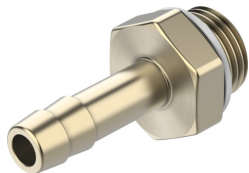

Data sheet

Feature	Value
Nominal width	11 mm
Type of seal on screwed plug	Sealing ring
Mounting position	Any
Design	Straight design
Pack size	1
Operating pressure for entire temperature range	-0.95 bar...16 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	1 - Low corrosion stress
LABS (PWIS) conformity	VDMA24364-B1/B2-L
Ambient temperature	-10 °C...60 °C
Max. tightening torque	40 Nm
Product weight	94 g
Pneumatic connection 1	External thread G3/4
Pneumatic connection 2	for pneumatic tubing inside diameter 13 mm
Note on materials	RoHS-compliant
Housing material	Brass